




2c


G6K(U)-2F-RF(-S/-T)

1GHz band/3 GHz band, ultra-small, low profile, low power dissipation, surface mount, two poles

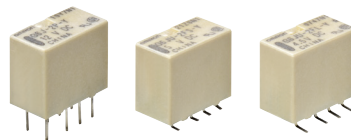


G6JY

ultra small, ultra thin, surface mount, two poles

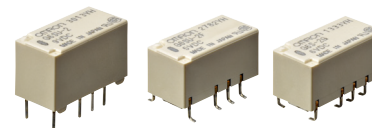


G6S

small, high sensitivity, thin, surface mount, two poles

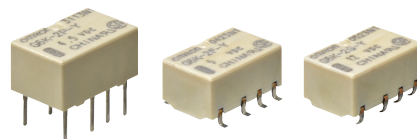


G6K

ultra small, low profile, low power consumption, surface mount, two poles

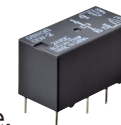

G5V2

general purpose, two poles

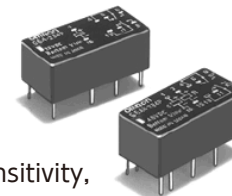


G6A-2

small, high sensitivity, sensitivity, two poles



G5V1

small, general purpose, one pole

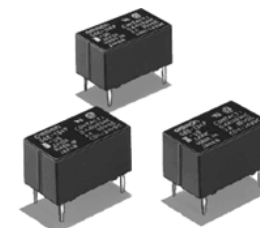

G6E

small, high-sensitivity, one pole

Contact structure

1c

1a

~1A

1A

2A

3A

Maximum Switching Current